 


Series 753-E FireLock® 300 psi Solenoid

PRODUCT DESCRIPTION




The Series 753-E FireLock solenoid is designed for use with Victaulic FireLock Preaction and Deluge devices that use electric actuation. Approved for a NEMA 4 classification the Series 753-E is rated to 300 psi/2065 kPa and is UL/ULC Listed and FM Approved for indoor or outdoor use. The solid brass construction provides protection against falling dirt, inclement weather, windblown dust, splashing and hose-directed water. The solenoid uses a 1/2"/21,3 mm NPT connection and is wired for 24 VDC service.



See Victaulic publication 10.01 for details.

DIMENSIONS

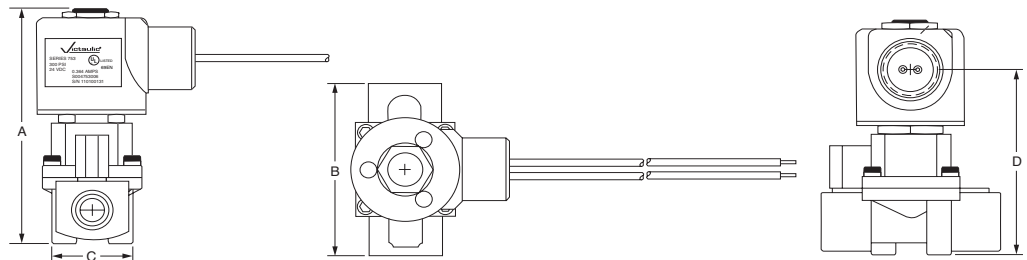

Size Inches/mm	Dimensions				Aprx. Weight Each Lbs./kg
	A	B	C	D	
1/2	3.75	2.75	1.50	2.96	1.2
21.3	95	70	38	75	0.5

MATERIAL SPECIFICATIONS

- Body:** Forged Brass
- Spring:** 300 Series Stainless Steel
- Seal:** Fluoroelastomer
- Diaphragm:** Fluoroelastomer
- Wiring:** 24 VDC
- Voltage:** 24 VDC
- Power Rating:** 8.7 Watts
- Resistance:** 66 Ohms
- Current:** .364 Amps

This product shall be manufactured by Victaulic or to Victaulic specifications. All products to be installed in accordance with current Victaulic installation/assembly instructions. Victaulic reserves the right to change product specifications, designs and standard equipment without notice and without incurring obligations.

