

FireLock® 300 psi Solenoid




SEE VICTAULIC PUBLICATION 10.01 FOR DETAILS

The FireLock solenoid is designed for use with Victaulic FireLock Preaction and Deluge devices that use electric actuation. Approved for NEMA 4 classification, the Series is rated to 300 psi/2065 kPa and is UL/ULC Listed and FM Approved for indoor or outdoor use. The solid brass construction provides protection against falling dirt, inclement weather, windblown dust, splashing and hose-directed water. The solenoid uses a 1/2"/21.3 mm NPT connection and is wired for 24VDC service.



DIMENSIONS

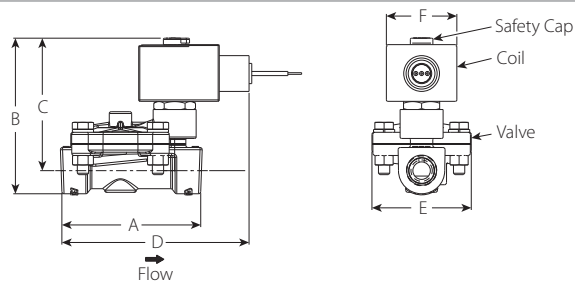

Size	Dimensions – Inches/mm				Approx. Weight Each
	Nominal Size Inches mm	A	B	C	
1/2 21.3	3.75 95	2.75 70	1.50 38	2.96 75	1.2 0.5

MATERIAL SPECIFICATIONS

- Body:** Forged Brass
- Spring:** 300 Series Stainless Steel
- Seal:** Fluoroelastomer
- Diaphragm:** Fluoroelastomer
- Wiring:** 24VDC
- Voltage:** 24VDC
- Power Rating:** 8.7 Watts
- Resistance:** 66 Ohms
- Current:** .364 Amps

JOB/OWNER

System No. _____
Location _____

CONTRACTOR

Submitted By _____
Date _____

ENGINEER

Spec Sect _____ Para _____
Approved _____
Date _____

FireLock® 300 psi Solenoid

INSTALLATION

Reference should always be made to the Installation, Maintenance, and Testing manual shipped with the product. Installation, Maintenance, and Testing manuals are included with each shipment of Victaulic products and are available in PDF format on our website at www.victaulic.com.

WARRANTY

Refer to the Warranty section of the current Price List or contact Victaulic for details.

NOTE

This product shall be manufactured by Victaulic or to Victaulic specifications. All products to be installed in accordance with current Victaulic installation/assembly instructions. Victaulic reserves the right to change product specifications, designs and standard equipment without notice and without incurring obligations.

For complete contact information, visit www.victaulic.com

30.63 3164 REV D UPDATED 08/2020

VICTAULIC IS A REGISTERED TRADEMARK OF VICTAULIC COMPANY. © 2020 VICTAULIC COMPANY. ALL RIGHTS RESERVED. PRINTED IN THE USA.

30.63

